


Set axial EAMM-A-S95-80G

Numar piesa: 8197478

FESTO

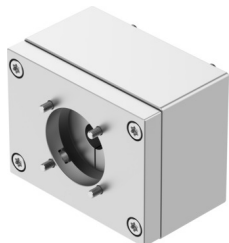

Fisa de date

Caracteristica	Valoare
Lungime nominala	85.5 mm
Pozitie de instalare	orice
Turatie max.	5500 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	128 kgmm ²
Cuplu transmisibil	75 Nm
Greutate produs	2920 g
Cod de interfata actuator	S95
Codul interfetei motor In	80G
Nota privind materialele	Conform RoHS