


## Set axial EAMM-A-D60-100A-G2

Numar piesa: 8197500

**FESTO**

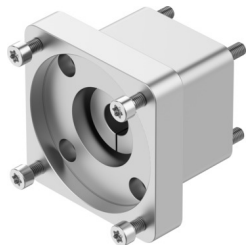

### Fisa de date

| Caracteristica               | Valoare                |
|------------------------------|------------------------|
| Lungime nominala             | 77.4 mm                |
| Pozitie de instalare         | orice                  |
| Turatie max.                 | 6000 1/min             |
| Conformitatea LABS           | VDMA24364-B2-L         |
| Temperatura de depozitare    | -25 °C...60 °C         |
| Umiditate relativa           | 0 - 95 %               |
| Tip de protectie             | IP40                   |
| Temperatura ambianta         | -10 °C...60 °C         |
| Momentul de inertie al masei | 34.8 kgmm <sup>2</sup> |
| Cuplu transmisibil           | 21 Nm                  |
| Greutate produs              | 1310 g                 |
| Cod de interfata actuator    | D60<br>D60C            |
| Codul interfetei motor In    | 100A                   |
| Nota privind materialele     | Conform RoHS           |