


Placa de alimentare VMPA-FB-SP-M12-V

Numar piesa: 8204604

FESTO

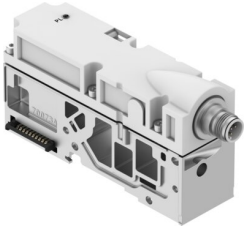

Fisa de date

Caracteristica	Valoare
Alimentarea max. cu energie electrica	4 A
Tensiune nominala de functionare CC	24 V
Fluctuatii de tensiune admise	+/- 25 %
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B1/B2-L
Tip de protectie	IP65
Temperatura ambianta	-5 °C...50 °C
Greutate produs	200 g
Conector electric	5 pini Conector rotund M12x1
Nota privind materialele	Conform RoHS
Material capac	Ranforsat cu PA
Material carcasa	Aluminiu turnat sub presiune