


# Set paralel EAMM-U-86-C50-10-108C-102-S5

Numar piesa: 8216600

FESTO

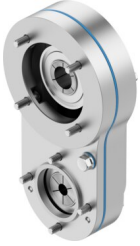

## Fisa de date

Caracteristica	Valoare
Dimensiune	86
Pozitie de instalare	orice
Raportul de transmisie	1:1
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 100 %
Tip de protectie	IP69K
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	174 kgmm <sup>2</sup>
Cuplu transmisibil	9.5 Nm
Greutate produs	3390 g
Cod de interfata actuator	C50-10
Codul interfetei motor In	108C
Nota privind materialele	Conform RoHS