


Kit axial EAMM-A-T42-40R

Numar piesa: 8217185

FESTO

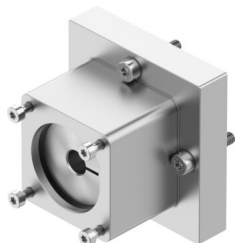

Fisa de date

Caracteristica	Valoare
Lungime nominala	46 mm
Pozitie de instalare	orice
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	3.2 kgmm ²
Cuplu transmisibil	7.5 Nm
Greutate produs	178 g
Cod de interfata actuator	T42
Codul interfetei motor In	40R 40RA
Nota privind materialele	Conform RoHS