


Cuplaj
EAMC-H-10-5-GB5-5
Numar piesa: 8228646

FESTO

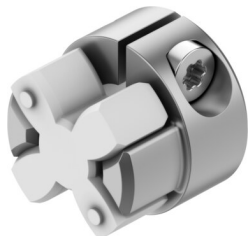

Fisa de date

Caracteristica	Valoare
Diametrul de montare 1	5 mm
Dimensiune	10
Lungime nominala	9.5 mm
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Temperatura ambianta	-25 °C...60 °C
Momentul de inertie al masei	0.022 kgmm ²
Cuplu transmisibil	0.6 Nm
Greutate produs	2 g
Nota privind materialele	Conform RoHS