


Cuplaj EAMC-H-15-7-GB8-6.35

Numar piesa: 8228649

FESTO

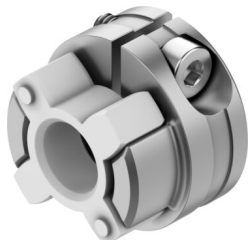

Fisa de date

Caracteristica	Valoare
Diametrul de montare 1	6.35 mm
Dimensiune	15
Lungime nominala	12.4 mm
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Temperatura ambianta	-25 °C...60 °C
Momentul de inertie al masei	0.191 kgmm ²
Cuplu transmisibil	2 Nm
Greutate produs	5 g
Nota privind materialele	Conform RoHS