


Cuplaj
EAMC-H-25-10-GB8-11
Numar piesa: 8228652

FESTO

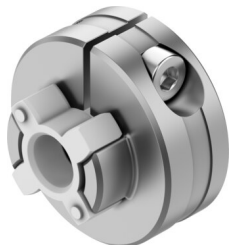

Fisa de date

Caracteristica	Valoare
Diametrul de montare 1	11 mm
Dimensiune	15/25
Lungime nominala	15.4 mm
Pozitie de instalare	orice
Turatie max.	10000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Temperatura ambianta	-25 °C...60 °C
Momentul de inertie al masei	1.04 kgmm ²
Cuplu transmisibil	2 Nm
Greutate produs	12 g
Nota privind materialele	Conform RoHS