


## Set axial EAMM-A-C42-8-80CA-S5

Numar piesa: 8230178

FESTO

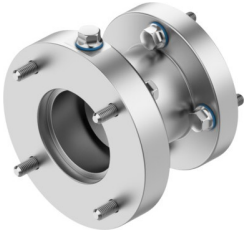

### Fisa de date

Caracteristica	Valoare
Lungime nominala	58 mm
Pozitie de instalare	orice
Raportul de transmisie	1:1
Turatie max.	8000 1/min
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 100 %
Tip de protectie	IP69K
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	5.87 kgmm <sup>2</sup>
Cuplu transmisibil	6.5 Nm
Greutate produs	860 g
Cod de interfata actuator	C42-8
Codul interfetei motor In	80CA
Nota privind materialele	Conform RoHS