


Kit axial EAMM-A-S60-90R

Numar piesa: 8234804

FESTO

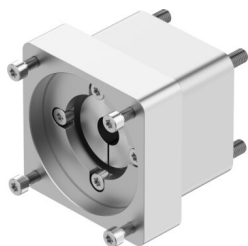

Fisa de date

Caracteristica	Valoare
Lungime nominala	75 mm
Pozitie de instalare	orice
Turatie max.	6000 1/min
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Momentul de inertie al masei	34.8 kgmm ²
Cuplu transmisibil	21 Nm
Greutate produs	1010 g
Cod de interfata actuator	S60
Codul interfetei motor In	90R 92RA
Nota privind materialele	Conform RoHS