


# Ventil cu parghie si rola RO-3-1/4-B

Numar piesa: 8991

FESTO

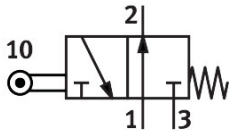

## Fisa de date

| Caracteristica                                       | Valoare                                                            |
|------------------------------------------------------|--------------------------------------------------------------------|
| Functie de ventil                                    | deschis 3/2 monostabil                                             |
| Tip de actionare                                     | mecanic                                                            |
| Debit nominal standard (normalizat conform DIN 1343) | 600 l/min                                                          |
| Racord pneumatic de lucru                            | G1/4                                                               |
| Presiune de lucru                                    | -0.95 bar...10 bar                                                 |
| Structura constructiva                               | Scaun-farfurie                                                     |
| Latimea nominala                                     | 7 mm                                                               |
| Tipul de comanda                                     | direct                                                             |
| Protectie la explozie                                | Zona 1 (ATEX)<br>Zona 2 (ATEX)<br>Zona 21 (ATEX)<br>Zona 22 (ATEX) |
| Conformitatea LABS                                   | VDMA24364-B1/B2-L                                                  |
| Temperatura ambianta                                 | -10 °C...60 °C                                                     |
| Fora de actionare                                    | 48 N                                                               |
| Greutate produs                                      | 230 g                                                              |
| Tipul de montare                                     | cu orificiu de trecere                                             |
| Conector pneumatic 1                                 | G1/4                                                               |
| Conexiune pneumatica 2                               | G1/4                                                               |
| Conector pneumatic 3                                 | G1/4                                                               |
| Material garnituri                                   | NBR                                                                |
| Material carcasa                                     | Aluminiu turnat sub presiune                                       |