

Valf adası

VDMA-01/02

Ürün numarası: 191403


FESTO

Type 14, with standard valves to ISO 15407/-1.

To configure first add product to the basket.

Depending on configuration, the technical data given on the data sheet and the relevant accessories might not match exactly for this product.

Products to be discontinued. Available until 2009.

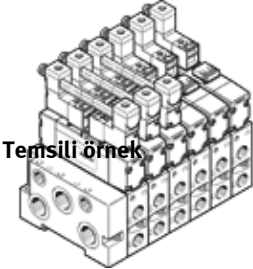

Temsili örnek

Bilgi sayfası

~ConfIndependentDatasheet

Özellik	Değer
Valf fonksiyonu	2x3/2 open/closed, single solenoid 2x3/2 closed, single solenoid 2x3/2 open, single solenoid 5/2 single solenoid 5/2 bistable 5/2 bistable-dominant 5/3 pressurised 5/3 exhausted 5/3 closed
Standart nominal debi	440 ... 1.000 l/min
Çalışma basıncı	-0,9 ... 16 bar
Electrical connection	Tekli bağlantı
Valf yerlerinin max. sayısı	16
Çevre sıcaklığı	-10 ... 60 °C
Width	18 mm 26 mm
Koruma sınıfı	IP65
Egzost hava fonksiyonu	kısılabilir
Tetikleme şekli	elektriksel
Valf adası tipi	14
Tasarım yapısı	Piston sürgüsü
Pilot basıncı beslemesi	harici dahili
Valf adası yapısı	modüler ve genişletilebilir
Pilot basıncı	3 ... 10 bar
Nominal çalışma gerilimi AC	24 V
Nominal çalışma gerilimi DC	12 V 24 V
CE mark (see declaration of conformity)	to EU directive low-voltage devices
Kullanım havası sıcaklığı	-10 ... 60 °C