

Cartridge fittings QSP, Quick Star, NPT

Datenblatt

Cartridge fittings QSPKG10

Material:


- Housing: Polyamide, fibreglass reinforced
- Release ring: Polyacetate
- Tubing seal: Nitrile rubber
- Tube retaining claw: High-alloy stainless steel

-  - Ambient temperature
-5 ... +60 °C

-  - Operating pressure
-0.95 ... +10 bar

Note on materials:
Conforms to RoHS

Certification:
Germanischer Lloyd

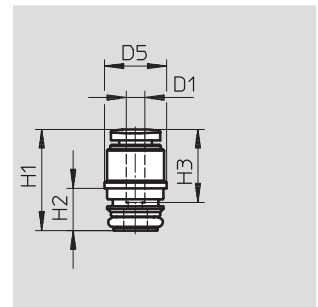

Dimensions and ordering data										
Tubing O.D.	Nominal size	D5 Ø	H1	H2	H3	CRC ¹⁾	Weight/piece [g]	Part No.	Type	PU ²⁾
D1	[mm]									
1/8	1.6	9.75	16.1	6.7	11.6	1	1.5	132852	QSPKG10-1/8-U  New	1
5/32	2.3	9.75	16.1	6.7	11.6	1	1.4	132624	QSPKG10-5/32-U  New	1
3/16	2.7	10.55	18.2	6.7	12	1	2.0	132625	QSPKG10-3/16-U  New	1
1/4	3.6	10.55	18.3	6.7	11.7	1	1.8	132626	QSPKG10-1/4-U  New	1

- 1) Corrosion resistance class 1 to Festo standard 940 070
Components requiring low corrosion resistance. Transport and storage protection. Parts that do not have primarily decorative surface requirements, e.g. in internal areas that are not visible or behind covers.
- 2) Packaging unit quantity.

Cartridge fittings QSP, Quick Star, NPT

Datenblatt

FESTO

Cartridge fittings QSPLK18

Material:


- Housing: Polyamide, fibreglass reinforced
- Release ring: Polyacetate
- Tubing seal: Nitrile rubber
- Tube retaining claw: High-alloy stainless steel

-  - Ambient temperature
-5 ... +60 °C

-  - Operating pressure
-0.95 ... +10 bar

Note on materials:
Conforms to RoHS

Certification:
Germanischer Lloyd

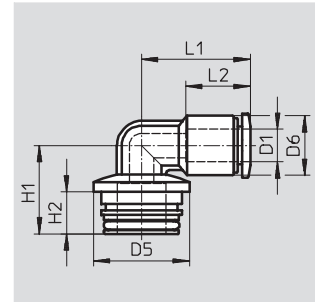

Dimensions and ordering data

Tubing O.D.	Nominal size	D5 Ø	D6 Ø	H1	H2	L1	L2	CRC ¹⁾	Weight/piece [g]	Part No.	Type	PU ²⁾
D1	[mm]											
3/8	6.5	17.7	17.7	19.6	7.75	29.5	20.2	1	10.9	132641	QSPLK18-3/8-U  New	10

1) Corrosion resistance class 1 to Festo standard 940 070

Components requiring low corrosion resistance. Transport and storage protection. Parts that do not have primarily decorative surface requirements, e.g. in internal areas that are not visible or behind covers.

2) Packaging unit quantity.

Cartridge fittings QSPLLK18

Material:


- Housing: Polyamide, fibreglass reinforced
- Release ring: Polyacetate
- Tubing seal: Nitrile rubber
- Tube retaining claw: High-alloy stainless steel

-  - Ambient temperature
-5 ... +60 °C

-  - Operating pressure
-0.95 ... +10 bar

Note on materials:
Conforms to RoHS

Certification:
Germanischer Lloyd

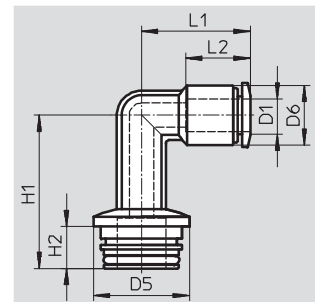

Dimensions and ordering data

Tubing O.D.	Nominal size	D5 Ø	D6 Ø	H1	H2	L1	L2	CRC ¹⁾	Weight/piece [g]	Part No.	Type	PU ²⁾
D1	[mm]											
3/8	6.2	17.7	17.7	38.3	7.75	29.5	20.2	1	12.2	132642	QSPLLK18-3/8-U  New	10

1) Corrosion resistance class 1 to Festo standard 940 070

Components requiring low corrosion resistance. Transport and storage protection. Parts that do not have primarily decorative surface requirements, e.g. in internal areas that are not visible or behind covers.

2) Packaging unit quantity.