


## Mounting plates VN-T

**FESTO**

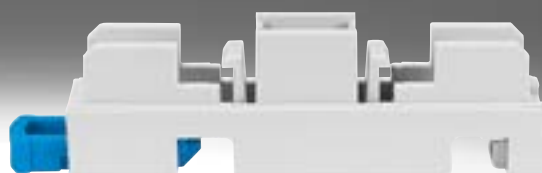

## Mounting plates VN-T

### Data sheet

#### Mounting plate VN-T...-NRH

For vacuum generator VN

→ Internet: vn

For mounting on H-rail or via through-hole

Ambient temperature: 0 ... +60°C

Material:


Plate VN-T2/T3/T4: Reinforced POM

Plate VN-T6: Reinforced PA

Slide: POM

RoHS-compliant

Free of copper and PTFE

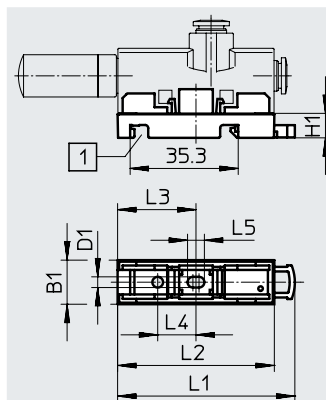

**Note**  
Horizontal wall mounting is not permitted with mounting plate VN-T6-BP-NRH.

[1] Suitable for H-rail 35x7.5 to DIN EN 50 022

#### Dimensions and ordering data

| Width [mm] | B1   | D1  | H1  | L1   | L2   | L3   | L4   | L5  | CRC <sup>1)</sup> | Weight [g] | Part no. | Type         |
|------------|------|-----|-----|------|------|------|------|-----|-------------------|------------|----------|--------------|
| 10         | 10.4 | 3.5 | 8   | 56.5 | 51   | 25.5 | 12.5 | 5.5 | 2                 | 3.5        | 196951   | VN-T2-BP-NRH |
| 14         | 14.4 | 3.5 | 8   | 57.9 | 51.2 | 25.6 | 12.5 | 5.5 | 2                 | 4.5        | 193641   | VN-T3-BP-NRH |
| 18         | 18.4 |     |     |      |      |      |      |     |                   | 5.5        | 195279   | VN-T4-BP-NRH |
| 24         | 24   | 4.3 | 7.3 | 98   | 91   | 45.5 | 32.5 | 6.3 | 2                 | 12.4       | 196956   | VN-T6-BP-NRH |

1) Corrosion resistance class CRC 2 to Festo standard FN 940070

Moderate corrosion stress. Indoor applications in which condensation can occur. External visible parts with primarily decorative surface requirements which are in direct contact with a normal industrial environment.

#### Mounting plate VN-T

For vacuum generator VN-A/B/M

→ Internet: vn


For wall mounting via through-hole for housing type T3/T4

Material:

Plate: Galvanised steel

RoHS-compliant

Free of copper and PTFE

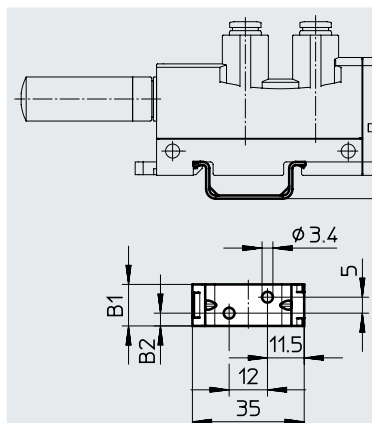

**Note**

Mounting plate VN-T6-BP-NRH should be used for housing type T6.

#### Dimensions and ordering data

| Width [mm] | B1 | B2 | CRC <sup>1)</sup> | Weight [g] | Part no. | Type     |
|------------|----|----|-------------------|------------|----------|----------|
| 14         | 13 | 4  | 2                 | 4.8        | 547436   | VN-T3-BP |
| 18         | 17 | 6  |                   | 6.4        | 547437   | VN-T4-BP |

1) Corrosion resistance class CRC 2 to Festo standard FN 940070

Moderate corrosion stress. Indoor applications in which condensation can occur. External visible parts with primarily decorative surface requirements which are in direct contact with a normal industrial environment.