


Electrical adapter NEFF with additional function

Technical data

Plug socket NEFF-S1G44LB

- Plug socket for operating an interlock-capable valve terminal interface in I-Port operation only

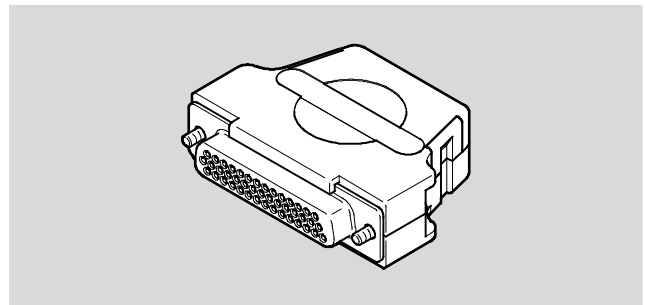

General technical data		
Max. tightening torque	[Nm]	0.24
Degree of protection EN 60529		IP40 (assembled)

Materials	
Note on materials	RoHS-compliant

Operating and environmental conditions		
Ambient temperature	[°C]	-5 ... +50

Dimensions Download CAD data → www.festo.com

Type	B1	H1	H2	L1
NEFF-S1G44LB	16	42.5	38	53.7

Ordering data		
	Part No.	Type
Plug socket	1589339	NEFF-S1G44LB