

Adapter for grippers

FESTO



Accessories

Adapter kit
HAPG, HMSV

Material:
Wrought aluminium alloy
RoHS-compliant

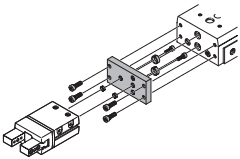
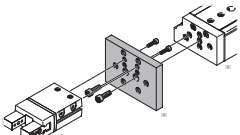
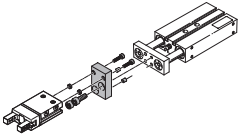
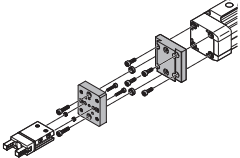


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper	Mounting option		Adapter kit		
		Size			CRC ¹⁾	Part no.	Type
							
DGST/DHPS	DGST	DHPS			DHAA		
	6	6	■	■	2	8161981	DHAA-G-G8-6-B18-6
	8	6	■	■		8161977	DHAA-G-G8-8-B18-6
	10	10	■	■		8161979	DHAA-G-G8-10-B18-10
	12	10	■	■		8161978	DHAA-G-G8-12-B18-10
	16	16	■	■		8161980	DHAA-G-G8-16-B18-16
	20	20	■	■		8161976	DHAA-G-G8-20-B18-20
	25	25	■	■		8161975	DHAA-G-G8-25-B18-25
DGSL/DHPS	DGSL	DHPS			HMSV		
	4, 6	6	■	■	2	548783	HMSV-53
	8, 10	10	■	■		548784	HMSV-54
	12, 16	16	■	■		548785	HMSV-55
	20, 25	20, 25	■	■		548786	HMSV-56
DPZ/DHPS	DPZ	DHPS			HAPG		
	10, 16	10	■	—	2	163250	HAPG-1
	16	16, 20	■	—		163251	HAPG-2
	20	16, 20	■	—		163252	HAPG-3
	25, 32	25	■	—		163253	HAPG-4
DGPL/DHPS	DGPL	DHPS			HMVA, HAPG, HMSV		
	Direct mounting				2		
	25, 32	6	■	■		196788	HMVA-DLA1 8/25
	40	6	■	■		192706	HAPG-37-S1
						196790	HMVA-DLA40
						192706	HAPG-37-S1
	25, 32	10	■	■		196788	HMVA-DLA1 8/25
	40	10	■	■		192705	HAPG-36-S1
						196790	HMVA-DLA40
						192705	HAPG-36-S1
	25, 32	16	■	■		196788	HMVA-DLA1 8/25
	40	16	■	■		193922	HAPG-37-S4
						196790	HMVA-DLA40
						193922	HAPG-37-S4

1) More information www.festo.com/x/topic/crc

Accessories

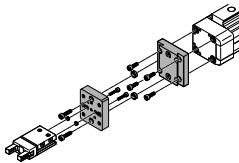
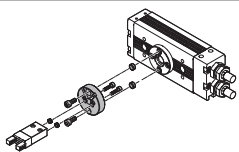
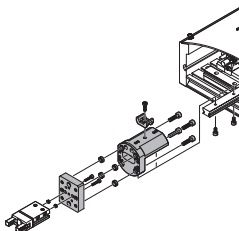
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit					Download CAD data → www.festo.com		
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
DGPL/DHPS	DGPL	DHPS			HMVA, HAPG, HMSV		
	Dovetail mounting						
	25	10	■	■	2	196788	HMVA-DLA18/25
						177767	HMSV-27
	40	10	■	■		196790	HMVA-DLA40
						177767	HMSV-27
	25	16	■	■		196788	HMVA-DLA18/25
						177768	HMSV-28
	40	16	■	■		196790	HMVA-DLA40
						177768	HMSV-28
	40	25	■	■		196790	HMVA-DLA40
				177769	HMSV-29		
40	35	■	■	196790	HMVA-DLA40		
				177770	HMSV-30		
DRRD/DHPS	DRRD	DHPS			DHAA		
	8	6	■	■	2	2808892	DHAA-G-Q11-8-B1-6
	10	6	■	■		2807644	DHAA-G-Q11-10-B1-6
	12	6	■	■		2805783	DHAA-G-Q11-12-B1-6
	12	10	■	■		2802687	DHAA-G-Q11-12-B1-10
	16	10	■	■		2190504	DHAA-G-Q11-16-B1-10
	16	16	■	■		2190393	DHAA-G-Q11-16-B1-16
	16	20	■	■		2187838	DHAA-G-Q11-16-B1-20
	20	16	■	■		2190284	DHAA-G-Q11-20-B1-16
	20	20	■	■		2187713	DHAA-G-Q11-20-B1-20
	20	25	■	■		2185820	DHAA-G-Q11-20-B1-25
	25	16	■	■		1471634	DHAA-G-Q11-25-B1-16
	25	20	■	■		1722652	DHAA-G-Q11-25-B1-20
	25	25	■	■		1725707	DHAA-G-Q11-25-B1-25
	32	25	■	■		2186909	DHAA-G-Q11-32-B1-25
	32	35	■	■		2187316	DHAA-G-Q11-32-B1-35
	35, 40	35	■	■		2187606	DHAA-G-Q11-35/40-B1-35
	HSP/DHPS	HSP	DHPS			HAPG	
	12	6	■	—	2	192709	HAPG-60-S1
						540881	HAPG-70-B
	16	6	■	—		192706	HAPG-37-S1
						540882	HAPG-71-B
	16	10	■	—		192705	HAPG-36-S1
						540882	HAPG-71-B
	25	10	■	—		192705	HAPG-36-S1
						540883	HAPG-72-B
	25	16	■	—		193922	HAPG-37-S4
				540883	HAPG-72-B		

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

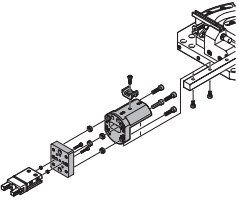
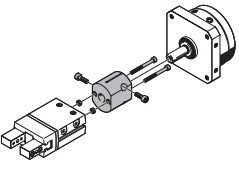
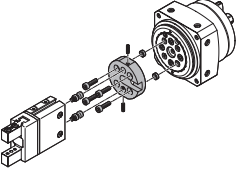
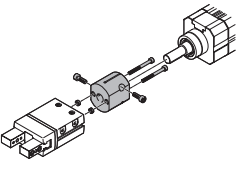


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
HSW/DHPS	HSW	DHPS			HAPG		
	12, 16	6	■	—	2	192706	HAPG-37-S1
						540882	HAPG-71-B
	12, 16	10	■	—		192705	HAPG-36-S1
						540882	HAPG-71-B
DSM/DHPS	DSM-...-FW	DHPS			HAPG		
	6, 8, 10	6	■	■	2	187568	HAPG-34
	DSM-...	DHPS					
	12	10	■	■		163266	HAPG-17
	16	10	■	■		163267	HAPG-18
	16	16, 20	■	■		163268	HAPG-19
	25	16, 20	■	■		163269	HAPG-20
	25	25	■	■		163270	HAPG-21
	32	25	■	■		163271	HAPG-22
DSM-...-HD/DHPS	DSM-...-HD	DHPS			DHAA		
	12	6	■	■	2	8071899	DHAA-G-R3-12-B18-6
	12	10	■	■		8072157	DHAA-G-R3-12-B18-10
	16	10	■	■		8071917	DHAA-G-R3-16-B18-10
	16	16	■	■		8079173	DHAA-G-R3-16-B18-16
	25	16, 20	■	■		8071956	DHAA-G-R3-25-B18-16
	32	25	■	■		8079208	DHAA-G-R3-32-B18-25
DSL/DHPS	DSL	DHPS			HAPG		
	16	10	■	■	2	163266	HAPG-17
	20	10	■	■		163267	HAPG-18
	20	16, 20	■	■		163268	HAPG-19
	25	16, 20	■	■		163269	HAPG-20
	25	25	■	■		163270	HAPG-21
	32	25	■	■		163271	HAPG-22

1) More information www.festo.com/x/topic/crc

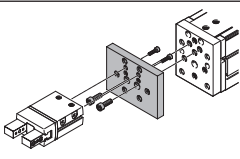
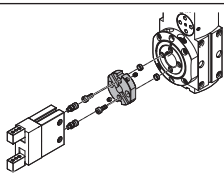
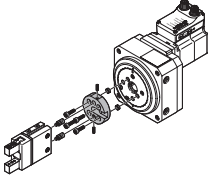
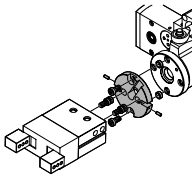
Accessories

Adapter kit
DHAA, HAPG, HMSV

Material:
Wrought aluminium alloy
RoHS-compliant

 **Note**

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit					Download CAD data → www.festo.com		
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
EGSL/DHPS	EGSL	DHPS			HMSV		
	35	6	■	■	2	548783	HMSV-53
						1088262	HMSV-70
	35	10	■	■		548784	HMSV-54
						1088262	HMSV-70
	45, 55	16	■	■		548785	HMSV-55
	75	20, 25	■	■		548786	HMSV-56
ERMB/DHPS	ERMB	DHPS			HAPG		
	20	16, 20	■	■	2	184479	HAPG-SD2-3
	25	16, 20	■	■		184482	HAPG-SD2-6
	20	25	■	■		184480	HAPG-SD2-4
	25	25	■	■		184483	HAPG-SD2-7
	32	35	■	■		184486	HAPG-SD2-10
ERMO/DHPS	ERMO	DHPS			DHAA		
	12	6	■	■	2	8071899	DHAA-G-R3-12-B18-6
	12	10	■	■		8072157	DHAA-G-R3-12-B18-10
	16	10	■	■		8071917	DHAA-G-R3-16-B18-10
	16	16	■	■		8079173	DHAA-G-R3-16-B18-16
	25	16, 20	■	■		8071956	DHAA-G-R3-25-B18-16
	32	25	■	■		8079208	DHAA-G-R3-32-B18-25
EHMB/DHPS	EHMB	DHPS			HAPG		
	20	35	■	■	2	184486	HAPG-SD2-10
	25, 32	35	■	■		526027	HAPG-SD2-21

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit DHAA

Material:
Wrought aluminium alloy
RoHS-compliant

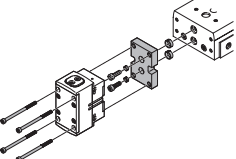
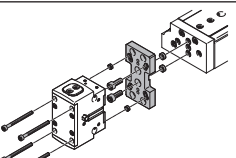
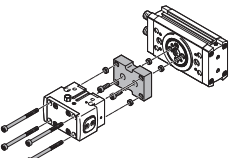


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
DGST/HGPD	DGST	HGPD			DHAA		
	10	16	—	■	2	8163132	DHAA-G-G8-10-B12-16
	12	20	—	■		8163129	DHAA-G-G8-12-B12-20
	16	25	—	■		8163133	DHAA-G-G8-16-B12-25
	20	35	—	■		8163131	DHAA-G-G8-20-B12-35
	25	40	—	■		8163130	DHAA-G-G8-25-B12-40
DGSL/HGPD	DGSL	HGPD			DHAA, HAPG		
	8, 10	16, 20	■	■	2	564957	DHAA-G-G6-8-B8-16
	12, 16	16, 20	■	■		564954	DHAA-G-G6-16-B8-16
	12, 16	25	■	■		564952	DHAA-G-G6-16-B8-25
	20, 25	25, 35	■	■		537175	HAPG-79
	20, 25	40	■	■		564951	DHAA-G-G6-20-B8-40
DRRD/HGPD	DRRD	HGPD			DHAA		
	12	16	■	■	2	2449935	DHAA-G-Q11-12-B12-16
	12	20	■	■		2449945	DHAA-G-Q11-12-B12-20
	16	16	■	■		2091914	DHAA-G-Q11-16-B12/B12G-16
	16	20	■	■		2091205	DHAA-G-Q11-16-B12-20
	16	25	■	■		2090715	DHAA-G-Q11-16-B12-25
	20	25	■	■		2088381	DHAA-G-Q11-20-B12-25
	20	35	■	■		2088008	DHAA-G-Q11-20-B12-35
	25	35	■	■		1714646	DHAA-G-Q11-25-B12-35
	25	40	■	■		1715576	DHAA-G-Q11-25-B12-40
	32	40	■	■		2092197	DHAA-G-Q11-32-B12-40
	35	40	■	■		2114998	DHAA-G-Q11-35-B12-40
	32	50	■	■		2124051	DHAA-G-Q11-32-B12-50
	35, 40	50	■	■		2124346	DHAA-G-Q11-3 5/40-B12-50
	40	63	■	■		2125614	DHAA-G-Q11-40-B12-63
	50	63	■	■		2352692	DHAA-G-Q11-50-B12-63
	50	80	■	■		2412840	DHAA-G-Q11-50-B12-80

1) More information www.festo.com/x/topic/crc

Accessories

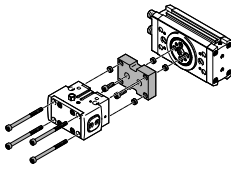
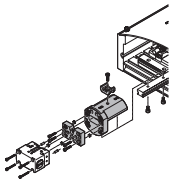
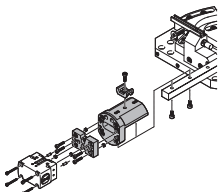
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit					Download CAD data → www.festo.com		
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
DRRD/HGPD	DRRD	HGPD-...-G1/G2			DHAA		
	12	16	■	■	2	2798991	DHAA-G-Q11-12-B12G-16
	12	20	■	■		2800963	DHAA-G-Q11-12-B12G-20
	16	20	■	■		2642948	DHAA-G-Q11-16-B12G-20
	16	25	■	■		2642941	DHAA-G-Q11-16-B12G-25
	20	25	■	■		2642953	DHAA-G-Q11-20-B12G-25
	20	35	■	■		2642961	DHAA-G-Q11-20-B12G-35
	25	35	■	■		2642962	DHAA-G-Q11-25-B12G-35
	25	40	■	■		2642966	DHAA-G-Q11-25-B12G-40
	32	40	■	■		2642967	DHAA-G-Q11-32-B12G-40
	32	50	■	■		2642969	DHAA-G-Q11-32-B12G-50
	35	40	■	■		2643047	DHAA-G-Q11-35-B12G-40
	35, 40	50	■	■		2643100	DHAA-G-Q11-3 5/40-B12G-50
	40	63	■	■		2643055	DHAA-G-Q11-40-B12G-63
	50	63	■	■		2643096	DHAA-G-Q11-50-B12G-63
	50	80	■	■		2643098	DHAA-G-Q11-50-B12G-80
HSP/HGPD	HSP	HGPD			DHAA, HAPG		
	12	16	■	—	2	564957	DHAA-G-G6-8-B8-16
						540881	HAPG-70-B
	16	16, 20	■	—		564957	DHAA-G-G6-8-B8-16
						540882	HAPG-71-B
	25	16, 20	■	—		564957	DHAA-G-G6-8-B8-16
						540883	HAPG-72-B
HSW/HGPD	HSW	HGPD			DHAA, HAPG		
	12, 16	16	■	—	2	564957	DHAA-G-G6-8-B8-16
						540882	HAPG-71-B
	16	20	■	—		564957	DHAA-G-G6-8-B8-16
						540882	HAPG-71-B

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG

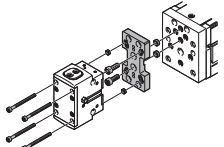
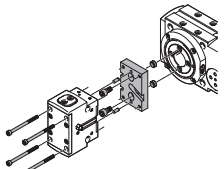
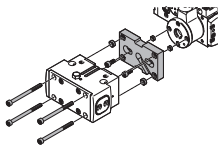
Material:
Wrought aluminium alloy
RoHS-compliant

 **Note**

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
	EGSL	HGPL					
	45, 55	25	■	■	2	564952	DHAA-G-G6-16-B8-25
	75	25, 35	■	■		537175	HAPG-79
	75	40	■	■		564951	DHAA-G-G6-20-B8-40
	ERMB	HGPL					
	20	25	■	■	2	537181	HAPG-SD2-25
	20, 25	35	■	■		537173	HAPG-SD2-23
	25, 32	40	■	■		537184	HAPG-SD2-26
	32	50	■	■		564956	DHAA-G-Q5-32-B8-50
	EHMB	HGPL					
	20	40	■	■	2	537184	HAPG-SD2-26
	20, 25, 32	50	■	■		564956	DHAA-G-Q5-32-B8-50
	25, 32	63	■	■		537188	HAPG-SD2-28

1) More information www.festo.com/x/topic/crc

Accessories

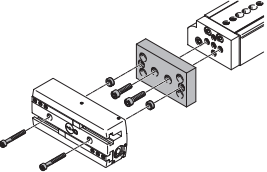
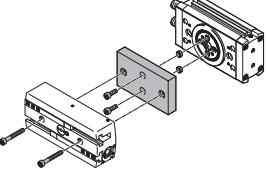
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit					Download CAD data → www.festo.com		
Combination	Drive	Gripper	Mounting option		Adapter kit		
	Size	Size			CRC ¹⁾	Part no.	Type
DGSL/HGPL	DGSL	HGPL			DHAA, HAPG		
	16	14-20	■	■	2	2406159	DHAA-G-G6-16-B6-14
	20, 25	14-20	■	■		2410181	DHAA-G-G6-20-B6-14
	16	14-40, 14-60, 14-80	■	■		538055	HAPG-89
	20, 25	14-40, 14-60, 14-80	■	■		539274	HAPG-90
	25	25	■	■		539274	HAPG-90
DRRD/HGPL	DRRD	HGPL			DHAA, HAPG		
	16	14-20	■	■	2	2019271	DHAA-G-Q11-16-B6-14-20
	16	14-40	■	■		2019618	DHAA-G-Q11-16-B6-14-40
	16	14-60, 14-80	■	■		2019640	DHAA-G-Q11-16-B6-14-60/80
	20	14-20	■	■		2018509	DHAA-G-Q11-20-B6-14-20
	20	14-40	■	■		2018553	DHAA-G-Q11-20-B6-14-40
	20	14-60, 14-80	■	■		2018986	DHAA-G-Q11-20-B6-14-60/80
	25	14-20	■	■		1813646	DHAA-G-Q11-25-B6-14-20
	25	14-40	■	■		1734087	DHAA-G-Q11-25-B6-14-40
	25	14-60, 14-80	■	■		2018453	DHAA-G-Q11-25-B6-14-60/80
	25	25-20, 25-40	■	■		1794882	DHAA-G-Q11-25-B6-25-20/40
	25	25-60, 25-80	■	■		2020149	DHAA-G-Q11-25-B6-25-60/80
	32	25-20, 25-40	■	■		2021733	DHAA-G-Q11-32-B6-25-20/40
	32	25-60, 25-80	■	■		2022377	DHAA-G-Q11-32-B6-25-60/80
	35	25-20, 25-40	■	■		2022892	DHAA-G-Q11-35-B6-25-20/40
	35	25-60, 25-80	■	■		2023095	DHAA-G-Q11-35-B6-25-60/80
	35, 40	40-20	■	■		2023665	DHAA-G-Q11-35/40-B6-40-20
	35, 40	40-40, 40-60	■	■		2024121	DHAA-G-Q11-35/40-B6-40-40/60
	35, 40	40-80, 40-100	■	■		2024947	DHAA-G-Q11-35/40-B6-40-80/100
	50	40-20	■	■		2387903	DHAA-G-Q11-50-B6-40-20
	50	40-40, 40-60, 40-80, 40-100	■	■		2431288	DHAA-G-Q11-50-B6-40-40/60/80/100
	50	63-60, 63-100, 63-150	■	■		2431624	DHAA-G-Q11-50-B6-63-60/100/150

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

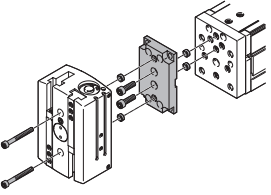
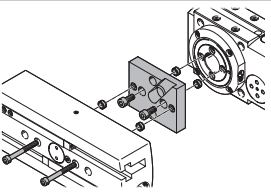
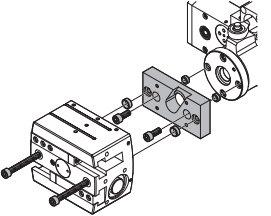


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
EGSL/HGPL	EGSL	HGPL			DHAA, HAPG		
	45, 55	14-20	■	■	2	2406159	DHAA-G-G6-16-B6-14
	75	14-20	■	■		2410181	DHAA-G-G6-20-B6-14
	45, 55	14-40, 14-60, 14-80	■	■		538055	HAPG-89
	75	14-40, 14-60, 14-80	■	■		539274	HAPG-90
	75	25	■	■		539274	HAPG-90
ERMB/HGPL	ERMB	HGPL			HAPG		
	20	14-40, 14-60, 14-80	■	■	2	537310	HAPG-SD2-31
	25, 32	25	■	■		537311	HAPG-SD2-29
EHMB/HGPL	EHMB	HGPL			DHAA, HAPG		
	25	40-20	■	■	2	2436852	DHAA-G-H2-25-B6-40
	20	25	■	■		537311	HAPG-SD2-29
	25	40-40, 40-60, 40-80, 40-100	■	■		537312	HAPG-SD2-30

1) More information www.festo.com/x/topic/crc

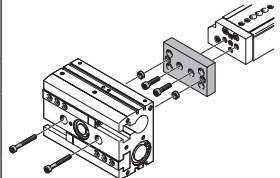
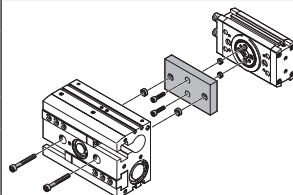
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Download CAD data → www.festo.com

Combination	Drive	Gripper	Mounting option		Adapter kit		
	Size	Size			CRC ¹⁾	Part no.	Type
							
DGSL/HPPL	DGSL	HPPL			DHAA, HAPG		
	16	16-40	■	■	2	2406159	DHAA-G-G6-16-B6-14
	20	16-40	■	■		2410181	DHAA-G-G6-20-B6-14
	25	16-40	■	■		2410181	DHAA-G-G6-20-B6-14
	16	16-80	■	■		538055	HAPG-89
	20	16-80	■	■		539274	HAPG-90
	25	16-80	■	■		539274	HAPG-90
	16	16-120, 16-160	■	■		538055	HAPG-89
	20	16-120, 16-160	■	■		539274	HAPG-90
	25	16-120, 16-160	■	■		539274	HAPG-90
	25	25-40, 25-80	■	■		539274	HAPG-90
	25	25-120, 25-160	■	■		539274	HAPG-90
DRRD/HPPL	DRRD	HPPL			DHAA		
	16	16-40	■	■	2	2019271	DHAA-G-Q11-16-B6-14-20
	20	16-40	■	■		2018509	DHAA-G-Q11-20-B6-14-20
	25	16-40	■	■		1813646	DHAA-G-Q11-25-B6-14-20
	16	16-80	■	■		2019618	DHAA-G-Q11-16-B6-14-40
	20	16-80	■	■		2018553	DHAA-G-Q11-20-B6-14-40
	25	16-80	■	■		1734087	DHAA-G-Q11-25-B6-14-40
	16	16-120, 16-160	■	■		2019640	DHAA-G-Q11-16-B6-14-60/80
	20	16-120, 16-160	■	■		2018986	DHAA-G-Q11-20-B6-14-60/80
	25	16-120, 16-160	■	■		2018453	DHAA-G-Q11-25-B6-14-60/80
	25	25-40, 25-80	■	■		1794882	DHAA-G-Q11-25-B6/B17-25-20/40
	32	25-40, 25-80	■	■		2021733	DHAA-G-Q11-32-B6/B17-25-20/40
	35	25-40, 25-80	■	■		2022892	DHAA-G-Q11-35-B6/B17-25-20/40
	25	25-120, 25-160	■	■		2020149	DHAA-G-Q11-25-B6-25-60/80
	32	25-120, 25-160	■	■		2022377	DHAA-G-Q11-32-B6-25-60/80
	35	25-120, 25-160	■	■		2023095	DHAA-G-Q11-35-B6-25-60/80
	35	40-40	■	■		2023665	DHAA-G-Q11-35/40-B6-40-20
	35	40-80, 40-120	■	■		2024121	DHAA-G-Q11-35/40-B6-40-40/60
	35	40-160, 40-200	■	■		2024947	DHAA-G-Q11-35/40-B6-40-80/100
	40	40-40	■	■		2023665	DHAA-G-Q11-35/40-B6-40-20
	40	40-80, 40-120	■	■		2024121	DHAA-G-Q11-35/40-B6-40-40/60
	40	40-160, 40-200	■	■		2024947	DHAA-G-Q11-35/40-B6-40-80/100
	50	40-40	■	■		2387903	DHAA-G-Q11-50-B6-40-20
	50	40-80, 40-120	■	■		2431288	DHAA-G-Q11-50-B6-40-40/60/80/100
	50	40-160, 40-200	■	■		2431288	DHAA-G-Q11-50-B6-40-40/60/80/100
	50	63-120, 63-200, 63-300	■	■		2431624	DHAA-G-Q11-50-B6-63-60/100/150

1) More information www.festo.com/x/topic/crc

Accessories

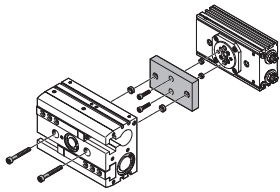
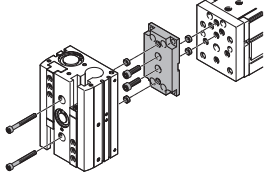
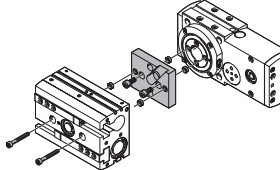
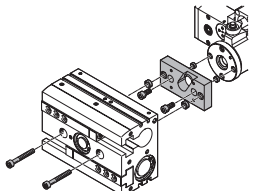
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

 **Note**
The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
	DRRS	HPPL			DHAA		
	16	16-40	■	■	2	2019271	DHAA-G-Q11-16-B6-14-20
	20	16-40	■	■		2018509	DHAA-G-Q11-20-B6-14-20
	25	16-40	■	■		1813646	DHAA-G-Q11-25-B6-14-20
	16	16-80	■	■		2019618	DHAA-G-Q11-16-B6-14-40
	20	16-80	■	■		2018553	DHAA-G-Q11-20-B6-14-40
	25	16-80	■	■		1734087	DHAA-G-Q11-25-B6-14-40
	16	16-120, 16-160	■	■		2019640	DHAA-G-Q11-16-B6-14-60/80
	20	16-120, 16-160	■	■		2018986	DHAA-G-Q11-20-B6-14-60/80
	25	16-120, 16-160	■	■		2018453	DHAA-G-Q11-25-B6-14-60/80
	25	25-40, 25-80	■	■		1794882	DHAA-G-Q11-25-B6/B17-25-20/40
	25	25-120, 25-160	■	■		2020149	DHAA-G-Q11-25-B6-25-60/80
	EGLS	HPPL			DHAA, HAPG		
	45	16-40	■	■	2	2406159	DHAA-G-G6-16-B6-14
	55	16-80	■	■		2406159	DHAA-G-G6-16-B6-14
	75	16-120, 16-160	■	■		2410181	DHAA-G-G6-20-B6-14
	45	16-40	■	■		538055	HAPG-89
	55	16-80	■	■		538055	HAPG-89
	75	16-120, 16-160	■	■		539274	HAPG-90
	45	16-40	■	■		538055	HAPG-89
	55	16-80	■	■		538055	HAPG-89
	75	16-120, 16-160	■	■		539274	HAPG-90
	ERMB	HPPL			HAPG		
	20	16-80	■	■	2	537310	HAPG-SD2-31
	20	16-120, 16-160	■	■		537310	HAPG-SD2-31
	25	25-40, 25-80	■	■		537311	HAPG-SD2-29
	25	25-120, 25-160	■	■		537311	HAPG-SD2-29
	EHMB	HPPL			HAPG		
	20	25-40, 25-80	■	■	2	537311	HAPG-SD2-29
	20	25-120, 25-160	■	■		537311	HAPG-SD2-29
	25	40-80, 40-120	■	■		537312	HAPG-SD2-30
	25	40-160, 40-200	■	■		537312	HAPG-SD2-30

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

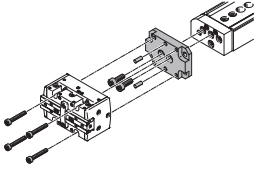
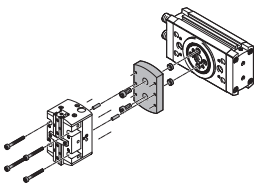


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
DGSL/HGPP	DGSL	HGPP			HAPG		
	8, 10	10	■	■	2	529017	HAPG-57
	12, 16	10	■	■		529018	HAPG-58
	12, 16	12	■	■		191266	HAPG-48
	20, 25	12	■	■		191267	HAPG-49
	20, 25	16	■	■		191269	HAPG-51
	20, 25	20	■	■		191270	HAPG-52
DRRD/HGPP	DRRD	HGPP			DHAA		
	16	10	■	■	2	2157955	DHAA-G-Q11-16-B5-10
	16	12	■	■		2154048	DHAA-G-Q11-16-B5-12
	20	10	■	■		2158267	DHAA-G-Q11-20-B5-10
	20	12	■	■		2152457	DHAA-G-Q11-20-B5-12
	20	16	■	■		2152074	DHAA-G-Q11-20-B5-16
	25	16	■	■		1722274	DHAA-G-Q11-25-B5-16
	25	20	■	■		1722461	DHAA-G-Q11-25-B5-20
	32	20	■	■		2177999	DHAA-G-Q11-32-B5-20
	32	25	■	■		2180764	DHAA-G-Q11-32-B5-25
	35	25	■	■		2180954	DHAA-G-Q11-35-B5-25
	35, 40	32	■	■		2181855	DHAA-G-Q11-3 5/40-B5-32

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

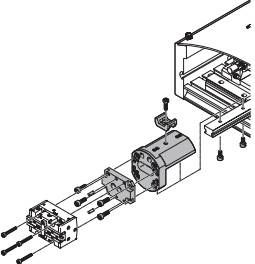
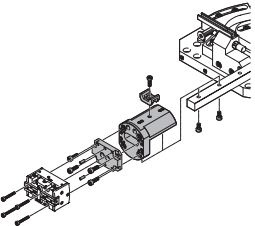
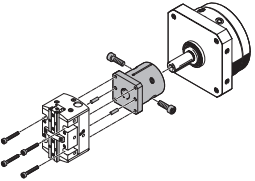
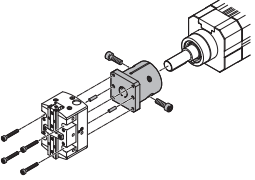


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
	HSP	HGPP			HAPG		
	16	10	■	—	2	529017	HAPG-57
						540882	HAPG-71-B
	25	10	■	—		529017	HAPG-57
						540883	HAPG-72-B
	16	12	■	—		191900	HAPG-54
						540882	HAPG-71-B
	25	12	■	—		191900	HAPG-54
						540883	HAPG-72-B
	25	16	■	—		191901	HAPG-55
						540883	HAPG-72-B
	HSW	HGPP			HAPG		
	12, 16	10	■	—	2	529017	HAPG-57
						540882	HAPG-71-B
	16	12	■	—		191900	HAPG-54
						540882	HAPG-71-B
	16	16	■	—		191901	HAPG-55
						540882	HAPG-71-B
	DSM	HGPP			HAPG		
	16	12	■	■	2	191258	HAPG-40
	25	12	■	■		191259	HAPG-41
	32	16	■	■		191260	HAPG-42
	40	20	■	■		191261	HAPG-43
	DSL	HGPP			HAPG		
	20	12	■	■	2	191258	HAPG-40
	25	12	■	■		191259	HAPG-41
	32	16	■	■		191260	HAPG-42
	40	20	■	■		191261	HAPG-43

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
HAPG, HMSV

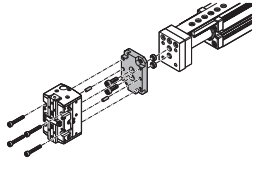
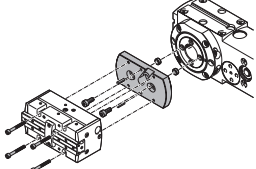
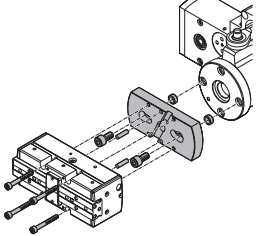
Material:
Wrought aluminium alloy
RoHS-compliant

 **Note**

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
EGSL/HGPP	EGSL	HGPP			HAPG, HMSV		
	35	10	■	■	2	1088262 529017	HMSV-70 HAPG-57
	45, 55	10	■	■		529018	HAPG-58
	45, 55	12	■	■		191266	HAPG-48
	75	12	■	■		191267	HAPG-49
	75	16	■	■		191269	HAPG-51
ERMB/HGPP	ERMB	HGPP			HAPG		
	20	10	■	■	2	526023	HAPG-SD2-17
	20	12	■	■		191255	HAPG-SD2-14
	20, 25	16	■	■		191256	HAPG-SD2-15
	25, 32	20	■	■		191257	HAPG-SD2-16
	32	25	■	■		526024	HAPG-SD2-18
EHMB/HGPP	EHMB	HGPP			HAPG		
	20	20	■	■	2	191257	HAPG-SD2-16
	20, 25, 32	25	■	■		526024	HAPG-SD2-18
	25, 32	32	■	■		526025	HAPG-SD2-19

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

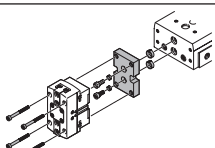
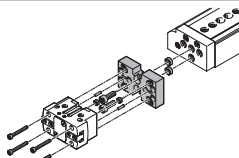
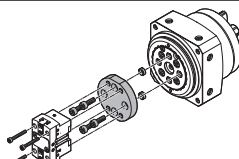


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
DGST/HGPT-B	DGST	HGPT-B			DHAA		
	10	16	—	■	2	8163575	DHAA-G-G8-10-B8-16
	12	20	—	■		8163574	DHAA-G-G8-12-B8-20
	16	25	—	■		8163577	DHAA-G-G8-16-B8-25
	20	35	—	■		8163576	DHAA-G-G8-20-B8-35
	25	40	—	■		8163573	DHAA-G-G8-25-B8-40
	DGST		HGPT-B-...-G1/G2			DHAA	
	10	16	—	■	2	8163580	DHAA-G-G8-10-B8G-16
	12	20	—	■		8163582	DHAA-G-G8-12-B8G-20
	16	25	—	■		8163579	DHAA-G-G8-16-B8G-25
	20	35	—	■		8163581	DHAA-G-G8-20-B8G-35
	25	40	—	■		8163578	DHAA-G-G8-25-B8G-40
DGSL/HGPT-B	DGSL	HGPT-B			DHAA, HAPG		
	8, 10	16, 20	■	■	2	564957	DHAA-G-G6-8-B8-16
	12, 16	16, 20	■	■		564954	DHAA-G-G6-16-B8-16
	12, 16	25	■	■		564952	DHAA-G-G6-16-B8-25
	20, 25	25, 35	■	■		537175	HAPG-79
	20, 25	40	■	■		564951	DHAA-G-G6-20-B8-40
DSM-...-HD/HGPT-B	DSM-...-HD	HGPT-B			DHAA		
	12	16	■	■	2	8079169	DHAA-G-R3-12-B8-16
	12	20	■	■		8079170	DHAA-G-R3-12-B8-20
	16	16	■	■		8079193	DHAA-G-R3-16-B8-16
	16	20	■	■		8079195	DHAA-G-R3-16-B8-20
	25	16	■	■		8079202	DHAA-G-R3-25-B8-16
	25	20	■	■		8079205	DHAA-G-R3-25-B8-20
	25	25	■	■		8079207	DHAA-G-R3-25-B8-25
	32	20	■	■		8079217	DHAA-G-R3-32-B8-20
	32	25	■	■		8079218	DHAA-G-R3-32-B8-25
	32	35	■	■		8079221	DHAA-G-R3-32-B8-35

1) More information www.festo.com/x/topic/crc

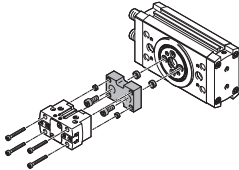
Accessories

Adapter kit
DHAAMaterial:
Wrought aluminium alloy
RoHS-compliant

Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Download CAD data → www.festo.com

Permissible drive/gripper combinations with adapter kit					Download CAD data → www.festo.com		
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
	DRRD	HGPT-B			DHAA		
	12	16	■	■	2	2449927	DHAA-G-Q11-12-B8/B8G-16
	12	20	■	■		2449921	DHAA-G-Q11-12-B8-20
	16	16	■	■		2091740	DHAA-G-Q11-16-B8/B8G-16
	16	20	■	■		2091577	DHAA-G-Q11-16-B8-20
	16	25	■	■		2090543	DHAA-G-Q11-16-B8-25
	20	25	■	■		2088114	DHAA-G-Q11-20-B8-25
	20	35	■	■		2087524	DHAA-G-Q11-20-B8-35
	25	35	■	■		1731604	DHAA-G-Q11-25-B8-35
	25	40	■	■		1731735	DHAA-G-Q11-25-B8-40
	32	40	■	■		2092070	DHAA-G-Q11-32-B8-40
	35	40	■	■		2114241	DHAA-G-Q11-35-B8-40
	32	50	■	■		2118750	DHAA-G-Q11-32-B8-50
	35, 40	50	■	■		2124990	DHAA-G-Q11-3 5/40-B8-50
	40	63	■	■		2125264	DHAA-G-Q11-40-B8-63
	50	63	■	■		2424526	DHAA-G-Q11-50-B8-63
	50	80	■	■		2424527	DHAA-G-Q11-50-B8-80
	DRRD	HGPT-B-G			DHAA		
	12	16	■	■	2	2449927	DHAA-G-Q11-12-B8/B8G-16
	12	20	■	■		2800827	DHAA-G-Q11-12-B8G-20
	16	16	■	■		2091740	DHAA-G-Q11-16-B8/B8G-16
	16	20	■	■		2595935	DHAA-G-Q11-16-B8G-20
	16	25	■	■		2596187	DHAA-G-Q11-16-B8G-25
	20	25	■	■		2596248	DHAA-G-Q11-20-B8G-25
	20	35	■	■		2596517	DHAA-G-Q11-20-B8G-35
	25	35	■	■		2597040	DHAA-G-Q11-25-B8G-35
	25	40	■	■		2597322	DHAA-G-Q11-25-B8G-40
	32	40	■	■		2597387	DHAA-G-Q11-32-B8G-40
	35	40	■	■		2597928	DHAA-G-Q11-35-B8G-40
	32	50	■	■		2597428	DHAA-G-Q11-32-B8G-50
	35, 40	50	■	■		2604977	DHAA-G-Q11-3 5/40-B8G-50
	40	63	■	■		2604813	DHAA-G-Q11-40-B8G-63
	50	63	■	■		2604845	DHAA-G-Q11-50-B8G-63
	50	80	■	■		2604887	DHAA-G-Q11-50-B8G-80

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

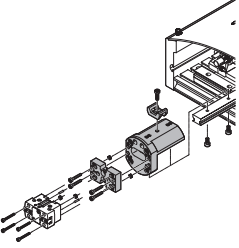
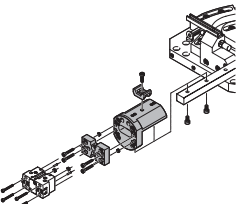
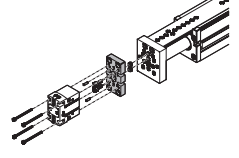
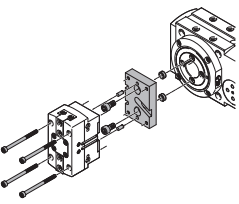


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
HSP/HGPT-B	HSP	HGPT-B			DHAA, HAPG		
	12	16	■	—	2	564957	DHAA-G-G6-8-B8-16
						540881	HAPG-70-B
	16	16, 20	■	—		564957	DHAA-G-G6-8-B8-16
						540882	HAPG-71-B
	25	16, 20	■	—		564957	DHAA-G-G6-8-B8-16
						540883	HAPG-72-B
HSW/HGPT-B	HSW	HGPT-B			DHAA, HAPG		
	12	16	■	—	2	564957	DHAA-G-G6-8-B8-16
						540882	HAPG-71-B
	16	16, 20	■	—		564957	DHAA-G-G6-8-B8-16
						540882	HAPG-71-B
EGSL/HGPT-B	EGSL	HGPT-B			DHAA, HAPG		
	45, 55	25	■	■	2	564952	DHAA-G-G6-16-B8-25
	75	40	■	■		564951	DHAA-G-G6-20-B8-40
	75	25, 35	■	■		537175	HAPG-79
ERMB/HGPT-B	ERMB	HGPT-B			DHAA, HAPG		
	20	25	■	■	2	537181	HAPG-SD2-25
	20, 25	35	■	■		537173	HAPG-SD2-23
	25, 32	40	■	■		537184	HAPG-SD2-26
	32	50	■	■		564956	DHAA-G-Q5-32-B8-50

1) More information www.festo.com/x/topic/crc

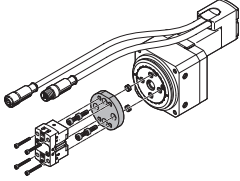
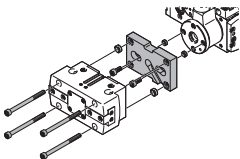
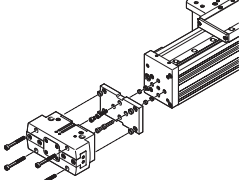
Accessories

Adapter kit
DHAA, HAPGMaterial:
Wrought aluminium alloy
RoHS-compliant

Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Download CAD data → www.festo.com

Permissible drive/gripper combinations with adapter kit						
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit	
					CRC ¹⁾	Part no. Type
ERMO/HGPT-B	ERMO	HGPT-B			DHAA	
	12	16	■	■	2	8079169 DHAA-G-R3-12-B8-16
	12	20	■	■		8079170 DHAA-G-R3-12-B8-20
	16	16	■	■		8079193 DHAA-G-R3-16-B8-16
	16	20	■	■		8079195 DHAA-G-R3-16-B8-20
	25	16	■	■		8079202 DHAA-G-R3-25-B8-16
	25	20	■	■		8079205 DHAA-G-R3-25-B8-20
	25	25	■	■		8079207 DHAA-G-R3-25-B8-25
	32	20	■	■		8079217 DHAA-G-R3-32-B8-20
	32	25	■	■		8079218 DHAA-G-R3-32-B8-25
	32	35	■	■		8079221 DHAA-G-R3-32-B8-35
EHMB/HGPT-B	EHMB	HGPT-B			DHAA, HAPG	
	20	40	■	■	2	537184 HAPG-SD2-26
	20, 25, 32	50	■	■		564956 DHAA-G-Q5-32-B8-50
	25, 32	63	■	■		537188 HAPG-SD2-28
ELCC/HGPT-B	ELCC	HGPT-B			DHAA	
	60	35	■	■	2	5162493 DHAA-G-E21-60-B8-35
	60	40	■	■		5162495 DHAA-G-E21-60-B8-40
	60	50	■	■		5162497 DHAA-G-E21-60-B8-50
	70	40	■	■		2092070 DHAA-G-Q11-32-B8-40
	70, 90	50	■	■		2118750 DHAA-G-Q11-32-B8-50
	70, 90, 110	63	■	■		5162500 DHAA-G-E21-70...110-B8-63
	90, 110	80	■	■		5162502 DHAA-G-E21-70...110-B8-80
	ELCC	HGPT-B-G			2	
	60	35	■	■		5162494 DHAA-G-E21-60-B8G-35
	60	40	■	■		5162496 DHAA-G-E21-60-B8G-40
	60	50	■	■		5162498 DHAA-G-E21-60-B8G-50
	70	40	■	■		2597387 DHAA-G-Q11-32-B8G-40
	70, 90	50	■	■		2597428 DHAA-G-Q11-32-B8G-50
	70, 90, 110	63	■	■		5162501 DHAA-G-E21-70...110-B8G-63
	90, 110	80	■	■		5162503 DHAA-G-E21-70...110-B8G-80

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG, HMSV, HMVA

Material:
Wrought aluminium alloy
RoHS-compliant

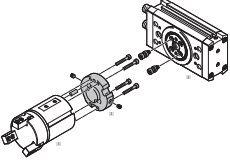
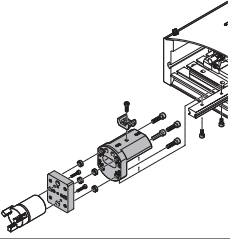
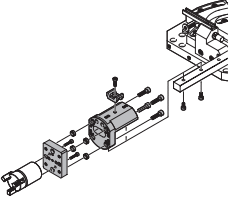


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Adapter kit		
			CRC ¹⁾	Part no.	Type
DRRD/DHDS	DRRD	DHDS	DHAA		
	12	16	2	2823512	DHAA-G-Q11-12-B4-16
	16	16		2136626	DHAA-G-Q11-16-B4-16
	16	32		2151381	DHAA-G-Q11-16-B4-32
	20	32		2136339	DHAA-G-Q11-20-B4-32
	25	32		1471583	DHAA-G-Q11-25-B4-32
	25	50		1731165	DHAA-G-Q11-25-B4-50
	32	50		1907040	DHAA-G-Q11-32-B4-50
	35	50		2135899	DHAA-G-Q11-35-B4-50
HSP/DHDS	HSP	DHDS	HAPG		
	16	16	2	192705	HAPG-36-S1
				540882	HAPG-71-B
	25	16		192705	HAPG-36-S1
				540883	HAPG-72-B
HSW/DHDS	HSW	DHDS	HAPG		
	16	16	2	192705	HAPG-36-S1
				540882	HAPG-71-B

1) More information www.festo.com/x/topic/crc

2) For DGEA-... only

Accessories

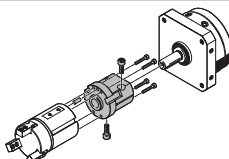
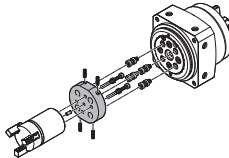
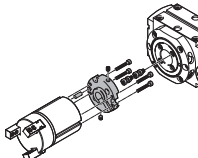
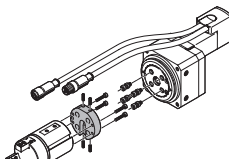
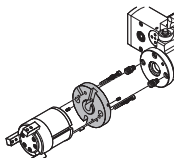
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit				Download CAD data → www.festo.com	
Combination	Drive Size	Gripper Size	Adaptr kit		
			CRC ¹⁾	Part no.	Type
DSM/DHDS	DSM	DHDS	HAPG		
	8, 10	16	2	187569	HAPG-35
	25	32		163272	HAPG-23
DSM-...-HD/DHDS	DSM-...-HD	DHDS	DHAA		
	12	16	2	8072232	DHAA-G-R3-12-B19-16
	16	16		8079175	DHAA-G-R3-16-B19-16
	16	32		8079191	DHAA-G-R3-16-B19-32
	25	32		8079196	DHAA-G-R3-25-B19-32
	25	50		8079199	DHAA-G-R3-25-B19-50
	32	50		8079210	DHAA-G-R3-32-B19-50
ERMB/DHDS	ERMB	DHDS	HAPG		
	20	32	2	184481	HAPG-SD2-5
	25	50		184484	HAPG-SD2-8
	32	50		184487	HAPG-SD2-11
ERMO/DHDS	ERMO	DHDS	DHAA		
	12	16	2	8072232	DHAA-G-R3-12-B19-16
	16	16		8079175	DHAA-G-R3-16-B19-16
	16	32		8079191	DHAA-G-R3-16-B19-32
	25	32		8079196	DHAA-G-R3-25-B19-32
	25	50		8079199	DHAA-G-R3-25-B19-50
	32	50		8079210	DHAA-G-R3-32-B19-50
EHMB/DHDS	EHMB	DHDS	HAPG		
	20	50	2	184487	HAPG-SD2-11
	25, 32	50		526026	HAPG-SD2-20

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

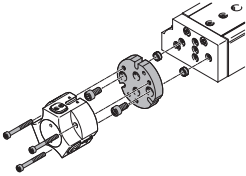
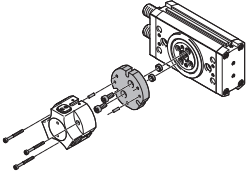


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Adapter kit			
			CRC ¹⁾	Part no.	Type	
DGSL/HGDD	DGSL	HGDD	DHAA			
	16, 20, 25	35	2	2371422	DHAA-G-G3-20-B13-35	
	20, 25	40		2373773	DHAA-G-H2-16-B13-40	
	25	50		2377625	DHAA-G-H2-20-B13-50	
	DGSL	HGDD-G1/G2	DHAA, HAPG			
	16, 20, 25	35	2	542436	HAPG-94	
	20, 25	40		542437	HAPG-95	
	25	50		2378415	DHAA-G-H2-20-B13G-50	
	DRRD/HGDD	DRRD	HGDD	DHAA		
		20	35	2	2075498	DHAA-G-Q11-20-B13-35
25		35	1718041		DHAA-G-Q11-25-B13-35	
25		40	1718564		DHAA-G-Q11-25-B13-40	
32		40	2077119		DHAA-G-Q11-32-B13-40	
32		50	2078975		DHAA-G-Q11-32-B13-50	
35		50	2079171		DHAA-G-Q11-35-B13-50	
35, 40		63	2079579		DHAA-G-Q11-3 5/40-B13-63	
DRRD		HGDD-G1/G2	DHAA			
20		35	2	2837144	DHAA-G-Q11-20-B13G-35	
25		35		2837169	DHAA-G-Q11-25-B13G-35	
25		40		2837182	DHAA-G-Q11-25-B13G-40	
32		40		2837254	DHAA-G-Q11-32-B13G-40	
32		50		2837269	DHAA-G-Q11-32-B13G-50	
35		50		2837283	DHAA-G-Q11-35-B13G-50	
35, 40		63		2837337	DHAA-G-Q11-3 5/40-B13G-63	

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA/HAPG

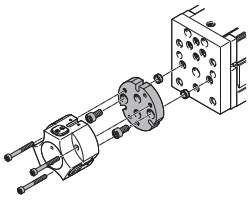
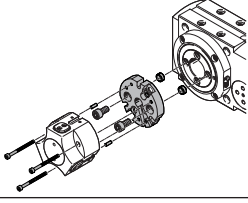
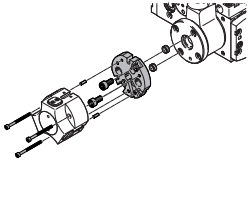
Material:
Wrought aluminium alloy
RoHS-compliant

 Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Adapter kit		
			CRC ¹⁾	Part no.	Type
	EGSL	HGDD	DHAA		
	45, 55, 75	35	2	2371422	DHAA-G-G3-20-B13-35
	75	40		2373773	DHAA-G-H2-16-B13-40
	75	50		2377625	DHAA-G-H2-20-B13-50
	EGSL	HGDD-G1/G2	DHAA, HAPG		
	45, 55, 75	35	2	542436	HAPG-94
	75	40		542437	HAPG-95
	75	50		2378415	DHAA-G-H2-20-B13G-50
	ERMB	HGDD	DHAA		
	20, 25, 32	35	2	2376297	DHAA-G-Q5-20-B13-35
	25, 32	40		2376728	DHAA-G-Q5-25-B13-40
	32	50		2377625	DHAA-G-H2-20-B13-50
	ERMB	HGDD-G1/G2	DHAA, HAPG		
	20, 25, 32	35	2	542441	HAPG-SD2-34
	25, 32	40		542442	HAPG-SD2-35
	32	50		2378415	DHAA-G-H2-20-B13G-50
	EHMB	HGDD	DHAA		
	20	35	2	2376297	DHAA-G-Q5-20-B13-35
	20	40		2376728	DHAA-G-Q5-25-B13-40
	20	50		2377625	DHAA-G-H2-20-B13-50
	EHMB	HGDD-G1/G2	DHAA, HAPG		
	20	35	2	542441	HAPG-SD2-34
	20	40		542442	HAPG-SD2-35
	20	50		2378415	DHAA-G-H2-20-B13G-50

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit HAPG

Material:
Wrought aluminium alloy
RoHS-compliant

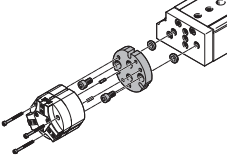
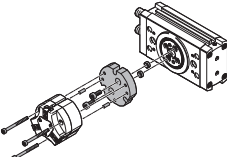
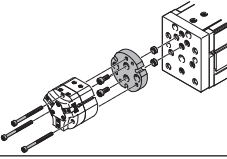
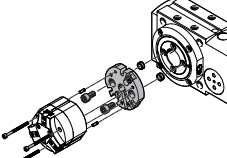
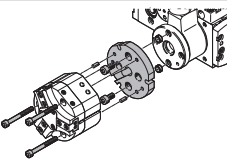


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Adapter kit CRC ¹⁾	Part no.	Type
DGSL/HGDT	DGSL	HGDT	HAPG		
	16	25	2	542439	HAPG-SD2-32
	16	35		542436	HAPG-94
	20, 25	35		548805	ZBV-9-7
	20, 25	40		542436	HAPG-94
	20, 25	40		542437	HAPG-95
	25	50		542443	HAPG-SD2-36
				548806	ZBV-12-9
DRRD/HGDT	DRRD	HGDT	DHAA		
	16	25	2	2079812	DHAA-G-Q11-16-B7/B7G-25
	20	25		2079695	DHAA-G-Q11-20-B7/B7G-25
	20	35		2077056	DHAA-G-Q11-20-B7-35
	25	35		1735057	DHAA-G-Q11-25-B7-35
	25	40		1735103	DHAA-G-Q11-25-B7-40
	32	40		2077253	DHAA-G-Q11-32-B7-40
	32	50		2077335	DHAA-G-Q11-32-B7-50
	35	50		2079063	DHAA-G-Q11-35-B7-50
	35, 40	63		2079274	DHAA-G-Q11-3 5/40-B7-63
	DRRD	HGDT-G	DHAA		
	20	35	2	2832455	DHAA-G-Q11-20-B7G-35
	25	35		2832483	DHAA-G-Q11-25-B7G-35
	25	40		2832545	DHAA-G-Q11-25-B7G-40
	32	40		2832575	DHAA-G-Q11-32-B7G-40
	32	50		2832600	DHAA-G-Q11-32-B7G-50
	35	50		2832617	DHAA-G-Q11-35-B7G-50
	35, 40	63		2832631	DHAA-G-Q11-3 5/40-B7G-63
EGSL/HGDT	EGSL	HGDT	HAPG		
	35	25	2	542433	HAPG-97
	45, 55	25		542439	HAPG-SD2-32
	45, 55, 75	35		542436	HAPG-94
	75	40		542437	HAPG-95
	75	50		542443	HAPG-SD2-36
ERMB/HGDT	ERMB	HGDT	HAPG		
	20, 25	25	2	542440	HAPG-SD2-33
	20, 25, 32	35		542441	HAPG-SD2-34
	25, 32	40		542442	HAPG-SD2-35
	32	50		542443	HAPG-SD2-36
EHMB/HGDT	EHMB	HGDT	HAPG		
	20	35	2	542441	HAPG-SD2-34
	20	40		542442	HAPG-SD2-35
	20	50		542443	HAPG-SD2-36

1) More information www.festo.com/x/topic/crc

Accessories

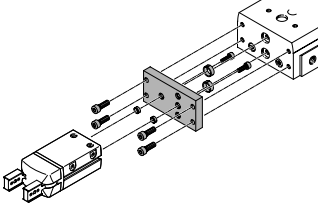
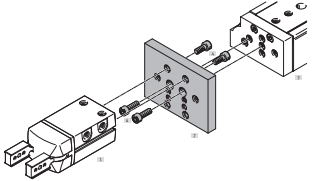
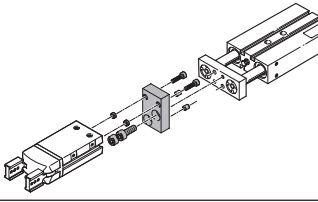
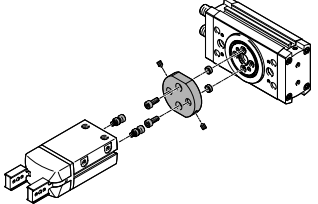
Adapter kit
HMSV, HAPG, DHAA

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit							
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
	DGST	DHRS			DHAA		
	10	10	■	■	2	8161907	DHAA-G-G8-10-B20-10
	12	16	■	■		8161909	DHAA-G-G8-12-B20-16
	16	16	■	■		8161908	DHAA-G-G8-16-B20-16
	20	25	■	■		8161905	DHAA-G-G8-20-B20-25
	25	32	■	■		8161906	DHAA-G-G8-25-B20-32
	DGSL	DHRS			HMSV		
	8, 10	10	■	■	2	548784	HMSV-54
	12, 16	16	■	■		548785	HMSV-55
	20, 25	25, 32	■	■		548786	HMSV-56
	DPZ	DHRS			HAPG		
	10, 16	16	■	—	2	163250	HAPG-1
	16	25	■	—		163251	HAPG-2
	20	25	■	—		163252	HAPG-3
	25, 32	32	■	—		163253	HAPG-4
	DRRD	DHRS			DHAA		
	8	10	■	■	2	2816591	DHAA-G-Q11-8-B2/B3-10
	10	10	■	■		2816068	DHAA-G-Q11-10-B2/B3-10
	12	10	■	■		2814790	DHAA-G-Q11-12-B2/B3-10
	12	16	■	■		2811183	DHAA-G-Q11-12-B2/B3-16
	16	16	■	■		1979085	DHAA-G-Q11-16-B2/B3-16
	16	25	■	■		1978889	DHAA-G-Q11-16-B2/B3-25
	20	25	■	■		1978443	DHAA-G-Q11-20-B2/B3-25
	20	32	■	■		1979912	DHAA-G-Q11-20-B2/B3-32
	25	25	■	■		1801802	DHAA-G-Q11-25-B2/B3-25
	25	32	■	■		1802969	DHAA-G-Q11-25-B2/B3-32
	32	32	■	■		1979992	DHAA-G-Q11-32-B2/B3-32
	32	40	■	■		1980014	DHAA-G-Q11-32-B2/B3-40
	35, 40	40	■	■		1980059	DHAA-G-Q11-3 5/40-B2/B3-40

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
HAPG, DHAA

Material:
Wrought aluminium alloy
RoHS-compliant

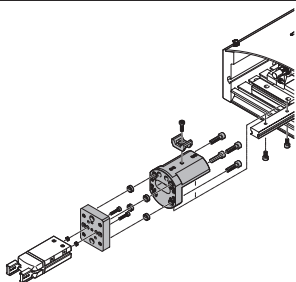
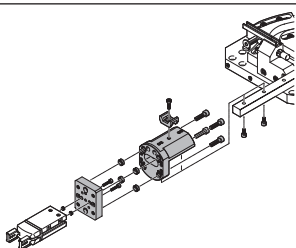
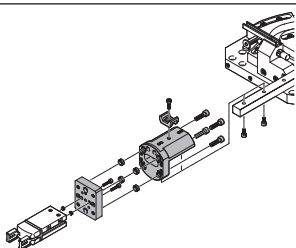
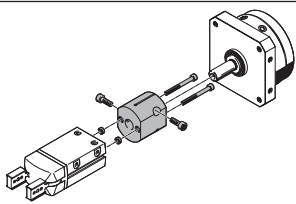
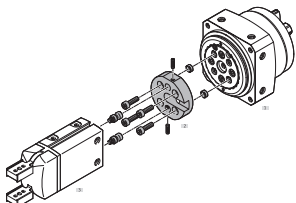


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
HSP/DHRS	HSP	DHRS			HAPG		
	12	10	■	—	2	192709	HAPG-60-S1
						540881	HAPG-70-B
	16	10	■	—		192706	HAPG-37-S1
						540882	HAPG-71-B
	16	16	■	—		192705	HAPG-36-S1
						540882	HAPG-71-B
	25	16	■	—		192705	HAPG-36-S1
						540883	HAPG-72-B
	25	25	■	—	2	193922	HAPG-37-S4
						540883	HAPG-72-B
HSW/DHRS	HSW	DHRS			HAPG		
	12, 16	10	■	—	2	192706	HAPG-37-S1
						540882	HAPG-71-B
	12, 16	16	■	—		192705	HAPG-36-S1
						540882	HAPG-71-B
DSM/DHRS	DSM-...-FW	DHRS			HAPG		
	6, 8, 10	10	■	■	2	187568	HAPG-34
	DSM-...	DHRS			HAPG		
	12	16	■	■	2	163266	HAPG-17
	16	16	■	■		163267	HAPG-18
	16	25	■	■		163268	HAPG-19
	25	25	■	■		163269	HAPG-20
	25	32	■	■		163270	HAPG-21
	32	32	■	■		163271	HAPG-22
DSM-...-HD/DHRS	DSM-...-HD	DHRS			DHAA		
	12	16	■	■	2	8072157	DHAA-G-R3-12-B18-10
	12	10	■	■		8072172	DHAA-G-R3-12-B20-10
	16	16	■	■		8071917	DHAA-G-R3-16-B18-10
	16	25	■	■		8079173	DHAA-G-R3-16-B18-16
	25	25	■	■		8071956	DHAA-G-R3-25-B18-16
	25	32	■	■		8079201	DHAA-G-R3-25-B20-32
	32	32	■	■		8079208	DHAA-G-R3-32-B18-25
	32	40	■	■		8079212	DHAA-G-R3-32-B20-40

1) More information www.festo.com/x/topic/crc

Accessories

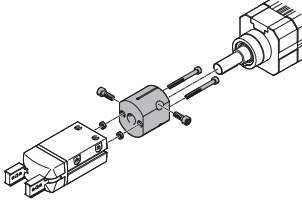
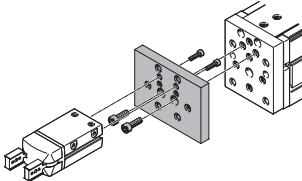
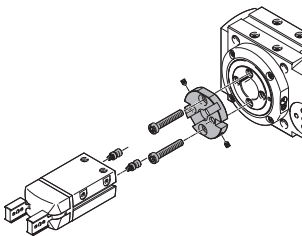
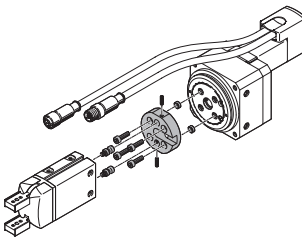
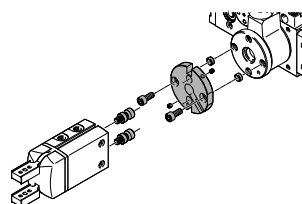
Adapter kit
HAPG, HMSV, DHAA

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit							
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
	DSL	DHRS			HAPG		
	16	16	■	■	2	163266	HAPG-17
	20	16	■	■		163267	HAPG-18
	20	25	■	■		163268	HAPG-19
	25	25	■	■		163269	HAPG-20
	25	32	■	■		163270	HAPG-21
	32	32	■	■		163271	HAPG-22
	EGSL	DHRS			HMSV		
	35	10	■	■	2	548784	HMSV-54
						1088262	HMSV-70
	45, 55	16	■	■		548785	HMSV-55
	75	25, 32	■	■		548786	HMSV-56
	ERMB	DHRS			HAPG		
	20	25	■	■	2	184479	HAPG-SD2-3
	25	25	■	■		184482	HAPG-SD2-6
	20	32	■	■		184480	HAPG-SD2-4
	25	32	■	■		184483	HAPG-SD2-7
	32	40	■	■		184486	HAPG-SD2-10
	ERMO	DHRS			DHAA		
	12	16	■	■	2	8072157	DHAA-G-R3-12-B18-10
	12	10	■	■		8072172	DHAA-G-R3-12-B20-10
	16	16	■	■		8071917	DHAA-G-R3-16-B18-10
	16	25	■	■		8079173	DHAA-G-R3-16-B18-16
	25	25	■	■		8071956	DHAA-G-R3-25-B18-16
	25	32	■	■		8079201	DHAA-G-R3-25-B20-32
	32	32	■	■		8079208	DHAA-G-R3-32-B18-25
	32	40	■	■		8079212	DHAA-G-R3-32-B20-40
	EHMB	DHRS			HAPG		
	20	40	■	■	2	184486	HAPG-SD2-10
	25, 32	40	■	■		526027	HAPG-SD2-21

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA

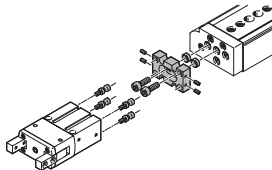
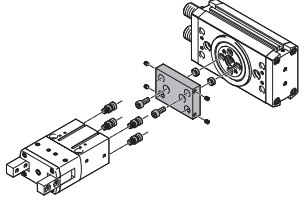
Material:
Wrought aluminium alloy
RoHS-compliant

 **Note**

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
	DGSL	HGRT			2		
	8, 10	16	■	■		1273902	DHAA-G-G6-8-B11-16
	12, 16	16	■	■		1467524	DHAA-G-G6-12-B11-16
	12, 16	20	■	■		1278364	DHAA-G-G6-12-B11-20
	20, 25	25	■	■		1468307	DHAA-G-G6-20-B11-25
	25	32	■	■		1280494	DHAA-G-G6-25-B11-32
	DRRD	HGRT			2		
	16	16	■	■		2185606	DHAA-G-Q11-16-B11-16
	20	20	■	■		2184467	DHAA-G-Q11-20-B11-20
	25	25	■	■		1741183	DHAA-G-Q11-25-B11-25
	25	32	■	■		1743177	DHAA-G-Q11-25-B11-32
	32	25	■	■		2184080	DHAA-G-Q11-32-B11-25
	32	32	■	■		2184322	DHAA-G-Q11-32-B11-32
	32	40	■	■		2184652	DHAA-G-Q11-32-B11-40
	35	40	■	■		2185436	DHAA-G-Q11-35-B11-40

1) More information www.festo.com/x/topic/crc

Accessories

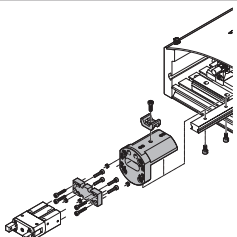
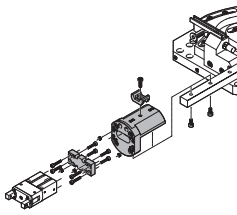
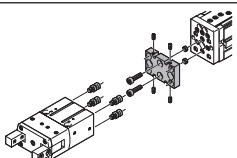
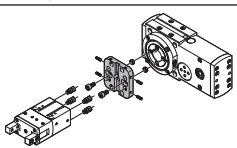
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit							Download CAD data → www.festo.com	
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type	
								
HSP/HGRT	HSP	HGRT			DHAA, HAPG			
	16	16	■	—	2	1274347	DHAA-G-H4-16-B11-16	
						540882	HAPG-71-B	
	25	16	■	—		1274347	DHAA-G-H4-16-B11-16	
						540883	HAPG-72-B	
HSW/HGRT	HSW	HGRT			DHAA, HAPG			
	12, 16	16	■	—	2	1274347	DHAA-G-H4-16-B11-16	
						540882	HAPG-71-B	
EGSL/HGRT	EGSL	HGRT			DHAA			
	45, 55	20	■	■	2	1278364	DHAA-G-G6-12-B11-20	
	45, 55	25	■	■		1279418	DHAA-G-E8-45-B11-25	
	75	25	■	■		1468307	DHAA-G-G6-20-B11-25	
	75	32	■	■		1280494	DHAA-G-G6-25-B11-32	
ERMB/HGRT	ERMB	HGRT			DHAA			
	20	20	■	■	2	1465263	DHAA-G-Q5-20-B11-20	
	25, 32	25	■	■		1279439	DHAA-G-Q5-25-B11-25	
	25, 32	32	■	■		1468949	DHAA-G-Q5-25-B11-32	

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
HAPG, HAPS, HMSV

Material:
Wrought aluminium alloy
RoHS-compliant

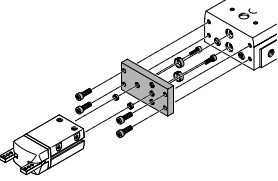
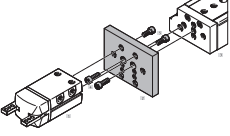
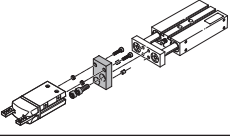
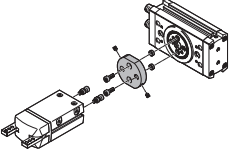


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
DGST/DHWS	DGST	DHWS			DHAA		
	10	10	■	■	2	8161907	DHAA-G-G8-10-B20-10
	12	16	■	■		8161909	DHAA-G-G8-12-B20-16
	16	16	■	■		8161908	DHAA-G-G8-16-B20-16
	20	25	■	■		8161905	DHAA-G-G8-20-B20-25
	25	32	■	■		8161906	DHAA-G-G8-25-B20-32
DGSL/DHWS	DGSL	DHWS			HMSV		
	8, 10	10	■	■	2	548784	HMSV-54
	12, 16	16	■	■		548785	HMSV-55
	20, 25	25, 32	■	■		548786	HMSV-56
DPZ/DHWS	DPZ	DHWS			HAPG		
	10, 16	16	■	—	2	163250	HAPG-1
	16	25	■	—		163251	HAPG-2
	20	25	■	—		163252	HAPG-3
	25, 32	32	■	—		163253	HAPG-4
DRRD/DHWS	DRRD	DHWS			DHAA		
	8	10	■	■	2	2816591	DHAA-G-Q11-8-B2/B3-10
	10	10	■	■		2816068	DHAA-G-Q11-10-B2/B3-10
	12	10	■	■		2814790	DHAA-G-Q11-12-B2/B3-10
	12	16	■	■		2811183	DHAA-G-Q11-12-B2/B3-16
	16	16	■	■		1979085	DHAA-G-Q11-16-B2/B3-16
	16	25	■	■		1978889	DHAA-G-Q11-16-B2/B3-25
	20	25	■	■		1978443	DHAA-G-Q11-20-B2/B3-25
	20	32	■	■		1979912	DHAA-G-Q11-20-B2/B3-32
	25	25	■	■		1801802	DHAA-G-Q11-25-B2/B3-25
	25	32	■	■		1802969	DHAA-G-Q11-25-B2/B3-32
	32	32	■	■		1979992	DHAA-G-Q11-32-B2/B3-32
	32	40	■	■		1980014	DHAA-G-Q11-32-B2/B3-40
	35, 40	40	■	■		1980059	DHAA-G-Q11-35/40-B2/B3-40

1) More information www.festo.com/x/topic/crc

Accessories

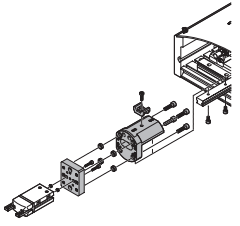
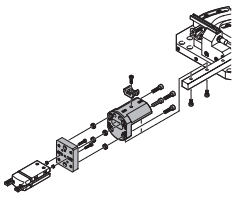
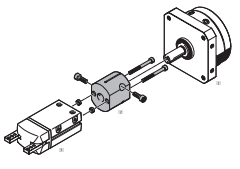
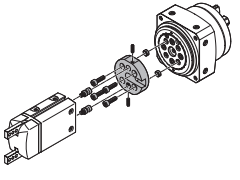
Adapter kit
DHAA, HAPG

Material:
Wrought aluminium alloy
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit					Download CAD data → www.festo.com		
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
HSP/DHWS	HSP	DHWS			HAPG		
	12	10	■	—	2	192709	HAPG-60-S1
	16	10	■	—		540881	HAPG-70-B
	16	16	■	—		192706	HAPG-37-S1
	25	16	■	—		540882	HAPG-71-B
	25	25	■	—		192705	HAPG-36-S1
						540882	HAPG-71-B
						192705	HAPG-36-S1
						540883	HAPG-72-B
						193922	HAPG-37-S4
						540883	HAPG-72-B
HSW/DHWS	HSW	DHWS			HAPG		
	12, 16	10	■	—	2	192706	HAPG-37-S1
	12, 16	16	■	—		540882	HAPG-71-B
						192705	HAPG-36-S1
						540882	HAPG-71-B
DSM/DHWS	DSM-...-FW	DHWS			HAPG		
	6, 8, 10	10	■	■	2	187568	HAPG-34
	DSM-...	DHWS			HAPG		
	12	16	■	■	2	163266	HAPG-17
	16	16	■	■		163267	HAPG-18
	16	25	■	■		163268	HAPG-19
	25	25	■	■		163269	HAPG-20
	25	32	■	■		163270	HAPG-21
	32	32	■	■		163271	HAPG-22
DSM-...-HD/DHWS	DSM-...-HD	DHWS			DHAA		
	12	16	■	■	2	8072157	DHAA-G-R3-12-B18-10
	12	10	■	■		8072172	DHAA-G-R3-12-B20-10
	16	16	■	■		8071917	DHAA-G-R3-16-B18-10
	16	25	■	■		8079173	DHAA-G-R3-16-B18-16
	25	25	■	■		8071956	DHAA-G-R3-25-B18-16
	25	32	■	■		8079201	DHAA-G-R3-25-B20-32
	32	32	■	■		8079208	DHAA-G-R3-32-B18-25
	32	40	■	■		8079212	DHAA-G-R3-32-B20-40

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG, HMSV

Material:
Wrought aluminium alloy
RoHS-compliant

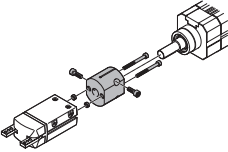
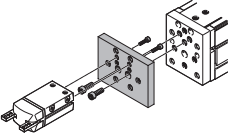
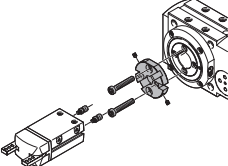
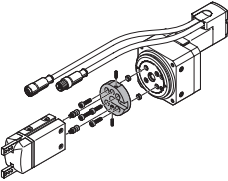
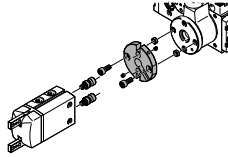


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit CRC ¹⁾	Part no.	Type
							
DSL/DHWS	DSL	DHWS			HAPG		
	16	16	■	■	2	163266	HAPG-17
	20	16	■	■		163267	HAPG-18
	20	25	■	■		163268	HAPG-19
	25	25	■	■		163269	HAPG-20
	25	32	■	■		163270	HAPG-21
	32	32	■	■		163271	HAPG-22
EGSL/DHWS	EGSL	DHWS			HMSV		
	35	10	■	■	2	548784	HMSV-54
						1088262	HMSV-70
	45, 55	16	■	■		548785	HMSV-55
	75	25, 32	■	■		548786	HMSV-56
ERMB/DHWS	ERMB	DHWS			HAPG		
	20	25	■	■	2	184479	HAPG-SD2-3
	25	25	■	■		184482	HAPG-SD2-6
	20	32	■	■		184480	HAPG-SD2-4
	25	32	■	■		184483	HAPG-SD2-7
	32	40	■	■		184486	HAPG-SD2-10
ERMO/DHWS	ERMO	DHWS			DHAA		
	12	16	■	■	2	8072157	DHAA-G-R3-12-B18-10
	12	10	■	■		8072172	DHAA-G-R3-12-B20-10
	16	16	■	■		8071917	DHAA-G-R3-16-B18-10
	16	25	■	■		8079173	DHAA-G-R3-16-B18-16
	25	25	■	■		8071956	DHAA-G-R3-25-B18-16
	25	32	■	■		8079201	DHAA-G-R3-25-B20-32
	32	32	■	■		8079208	DHAA-G-R3-32-B18-25
	32	40	■	■		8079212	DHAA-G-R3-32-B20-40
EHMB/DHWS	EHMB	DHWS			HAPG		
	20	40	■	■	2	184486	HAPG-SD2-10
	25, 32	40	■	■		526027	HAPG-SD2-21

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
HMVA, HMSV, HAVB

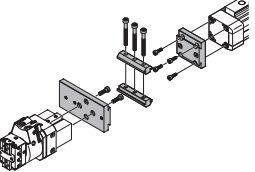
Material:
 Wrought aluminium alloy
 RoHS-compliant

**Note**

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive	Gripper	Mounting option		Adapter kit		
	Size	Size			CRC ¹⁾	Part no.	Type
DGPL/HGDS	DGPL	HGDS			HMSV, HMVA		
	DGPL-25	12, 16, 20	■	■	2	177653	HMSV-7
						534290	HMSV-38
						196788	HMVA-DLA1 8/25
	DGPL-40	12, 16, 20	■	■		177653	HMSV-7
						534290	HMSV-38
						196790	HMVA-DLA40

1) More information www.festo.com/x/topic/crc

Accessories

Adapter kit
DHAA, HAPG, HMSV

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant

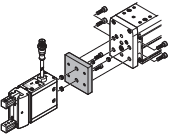
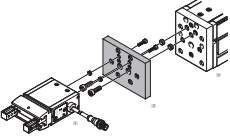
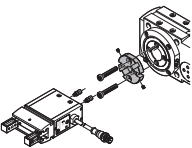
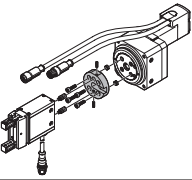
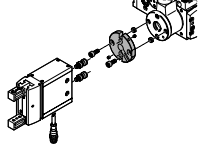
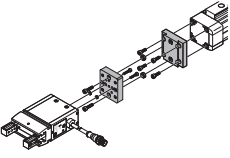


Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit

Download CAD data → www.festo.com

Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
EGSC/EHPS	EGSC	EHPS			HMSV		
	60	16, 20	■	■	2	8106581	DHAA-G-E8-60-B18-16
EGSL/EHPS	EGSL	EHPS			HMSV		
	45, 55	16	■	■	2	548785	HMSV-55
	75	20, 25	■	■		548786	HMSV-56
	ERMB	EHPS			HAPG		
	20	16, 20	■	■	2	184479	HAPG-SD2-3
	25	16, 20	■	■		184482	HAPG-SD2-6
	20	25	■	■		184480	HAPG-SD2-4
	25	25	■	■		184483	HAPG-SD2-7
ERMO/EHPS	ERMO	EHPS			DHAA		
	16	16	■	■	2	8079173	DHAA-G-R3-16-B18-16
	25	16, 20	■	■		8071956	DHAA-G-R3-25-B18-16
	32	20	■	■		8079214	DHAA-G-R3-32-B18-20
	32	25	■	■		8079208	DHAA-G-R3-32-B18-25
EHMB/EHPS	EHMB	EHPS			HAPG		
	25, 32	25	■	■	2	8078739	DHAA-G-H1-25-B18-25
DGPL/EHPS	DGPL	EHPS			HMVA, HAPG, HMSV		
	Direct mounting						
	25, 32	16	■	■	2	196788	HMVA-DLA18/25
						193922	HAPG-37-S4
	40	16	■	■		196790	HMVA-DLA40
						193922	HAPG-37-S4
	Dovetail mounting						
	25	16	■	■	2	196788	HMVA-DLA18/25
						177768	HMSV-28
	40	16, 20	■	■		196790	HMVA-DLA40
						177768	HMSV-28
	40	25	■	■		196790	HMVA-DLA40
						177769	HMSV-29

1) More information www.festo.com/x/topic/crc

Accessories

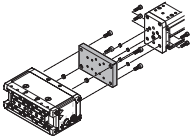
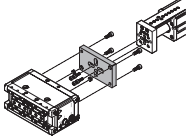
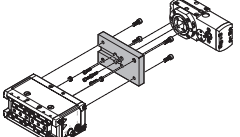
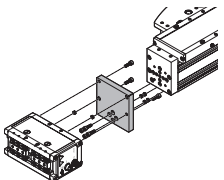
Adapter kit
DHAA, HAPG, HMSV

Material:
Wrought aluminium alloy
Free of copper and PTFE
RoHS-compliant



Note

The kit includes the individual mounting interface as well as the necessary mounting material.

Permissible drive/gripper combinations with adapter kit					Download CAD data → www.festo.com		
Combination	Drive Size	Gripper Size	Mounting option		Adapter kit		
					CRC ¹⁾	Part no.	Type
EGSC/HEPP	EGSC	HEPP			HMSV		
	32	28	■	■	2	8150924	DHAA-G-E19-32-B24-28
	45	28	■	■		8178992	DHAA-G-E19-45-B24-28
	60	28	■	—		8178994	DHAA-G-E19-60-B24-28
	45	36	■	■		8150922	DHAA-G-E19-45-B24-36
	60	36	■	—		8178996	DHAA-G-E19-60-B24-36
EGSL/HEPP	EGSL	HEPP			HMSV		
	35	28	■	■	2	8150917	DHAA-G-E8-35-B24-28
	45	28	■	■		8150920	DHAA-G-E8-45-B24-28
	55	28	■	■		8178987	DHAA-G-E8-55-B24-28
	75	28	■	—		8178988	DHAA-G-E8-75-B24-28
	55	36	■	■		8150914	DHAA-G-E8-55-B24-36
	75	36	■	—		8178990	DHAA-G-E8-75-B24-36
ERMB/HEPP	ERMB	HEPP			HAPG		
	20	28	■	■	2	8154540	DHAA-G-R1-20-B24-28
	25	28	■	■		8154544	DHAA-G-R1-25-B24-28
	20	36	■	■		8154542	DHAA-G-R1-20-B24-36
	25	36	■	■		8179001	DHAA-G-R1-25-B24-36
	25	42	■	■		8154546	DHAA-G-R1-25-B24-42
	32	42	■	■		8154548	DHAA-G-R1-32-B24-42
ELCC/HEPP	ELCC	HEPP			DHAA		
	60	28	■	■	2	8150928	DHAA-G-E21-60-B24-28
	70	28	■	■		8150926	DHAA-G-E21-70-B24-28
	60	36	■	■		8150930	DHAA-G-E21-60-B24-36
	70	36	■	—		8150935	DHAA-G-E21-70-B24-36
	90	36	■	■		8150932	DHAA-G-E21-90-B24-36
	70	42	■	■		8150953	DHAA-G-E21-70-B24-42
	90	42	■	■		8150939	DHAA-G-E21-90-B24-42
	110	42	■	■		8178999	DHAA-G-E21-110-B24-42

1) More information www.festo.com/x/topic/crc